

RE 18331-02/04.23

Replaces: RE 18331-02/07.12

Flow control, restrictor


Common cavity

Cartridge style in manifold

ST-C-C

ON.02 - K - X - Y - 00 - W

Dimensions

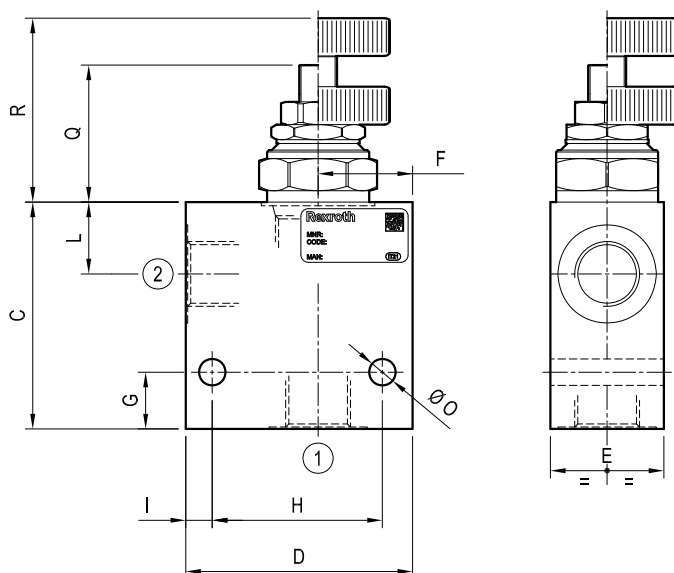

Technical data

Max flow:	up to 150 l/min	(39 gpm)
Max operating pressure for steel body:	350 bar	(5000 psi)
Max operating pressure for aluminium body:	210 bar	(3000 psi)

To order only manifold see data sheet RE 18325-85

 


Table “Y”

[illegible]

Cartridge style

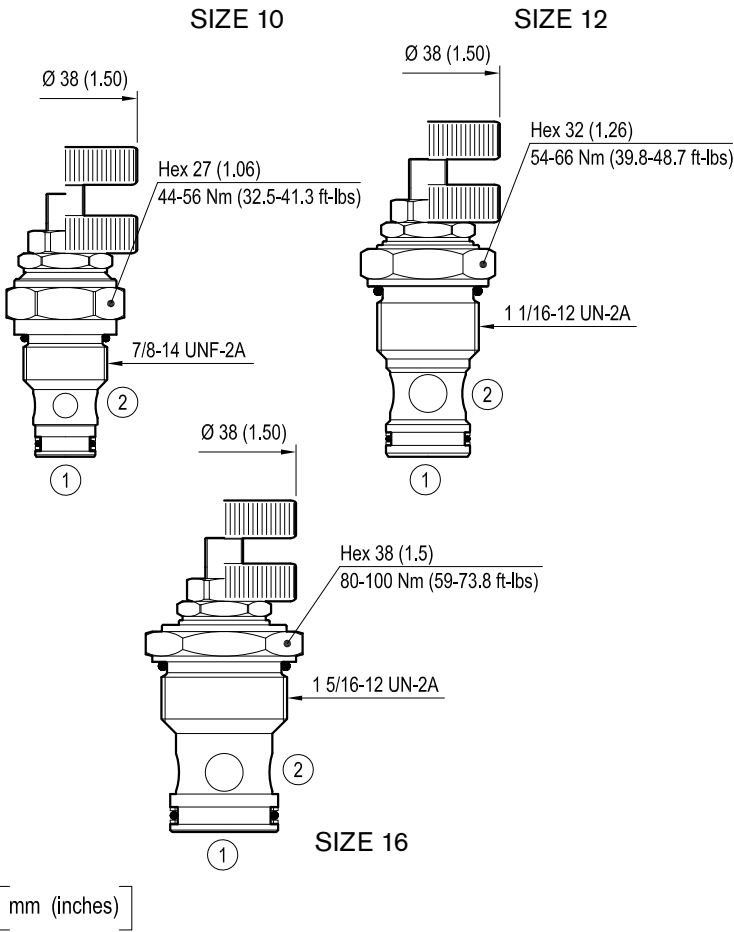


Table “K”

CARTRIDGE CODE	K						
	OD	21	01	X	36	00	ST-C-10A
	OD	21	01	X	89	00	ST-C-12A
	OD	21	01	X	75	00	ST-C-16A

Table “X”


X	ADJUSTMENTS	
03	Leakproof hex. socket screw	
04	Handknob and locknut	

CARTRIDGE TECHNICAL DATA


Common cavity: **CA-10A-2N / CA-12A-2N / CA-16A-2N**
For other details see data sheet RE 18321-27, RE 18321-28, and RE 18321-29

Performance graphs

SIZE 10

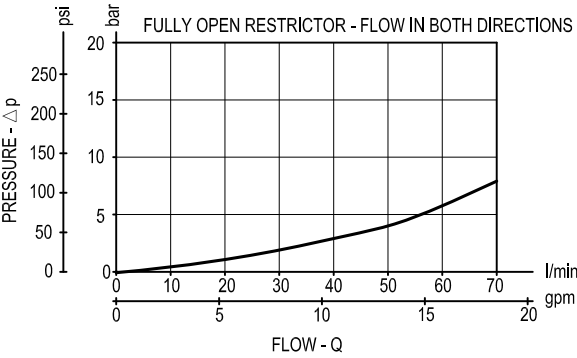

SIZE 12

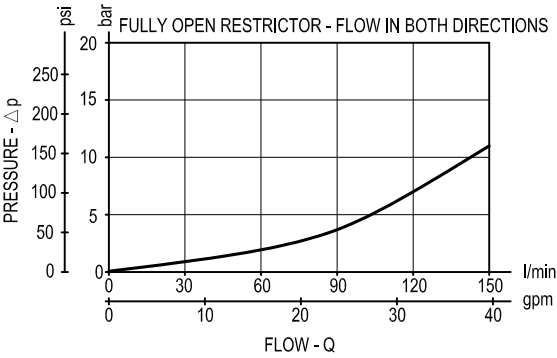

SIZE 16

