

Relief, direct acting poppet type,
pressure compensated


Special cavity

Cartridge style in manifold

VSC-30-CC

OR.10.27 - X - Y - Z

Dimensions

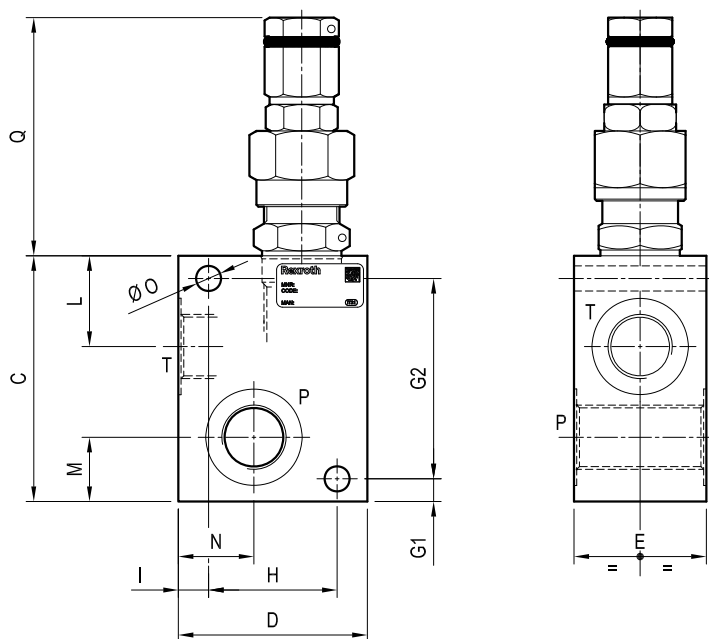

Technical data

Max flow:	up to 30 l/min	(8 gpm)
Max operating pressure for steel body:	350 bar	(5000 psi)
Max operating pressure for aluminium body:	210 bar	(3000 psi)


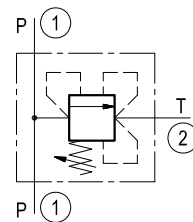


Table “Y”

[illegible]

Performance graph

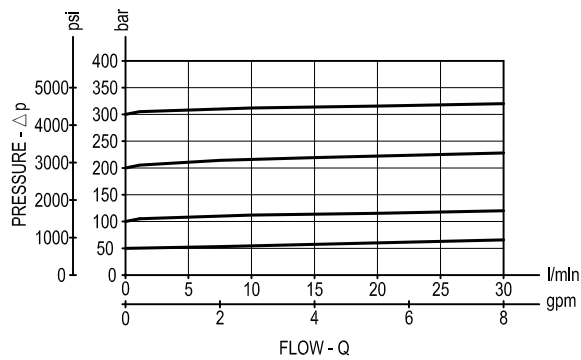

Ordering code

OR.10.27	X	Y	Z
Manifold with relief, direct acting poppet type, pressure compensated Special cavity			Settings - Springs (see table Z on page 2)
Cartridge style - Adjustments (see table X on page 2)		Manifold style - Dimensions and port sizes (see table Y on page 1)	

Preferred types (readily available)

Type	Material number	Type	Material number
OR102703022000	R934003317		
OR102703030500	R934003931		

Further types available by request